


Storage, Polyethylene, Conical-bottom, Gasket Lid w/Stand

The conical bottom polyethylene storage tank (55 to 2,000 gallons) insures complete tank drainage for cleaning and sanitization operations. The tank is constructed of virgin high-density FDA approved polyethylene and supported by a structural steel stand painted with an acid resistant epoxy.

- Each tank includes seven factory installed polyethylene half coupling fittings welded and tapered into the tank wall
- Polyethylene tank lid with neoprene flat gasket seal is bolted to the tank for air tight access to the tank interior
- 3-position level controller, hydrophobic vent filter, nitrogen blanket system and vacuum/pressure relief valve optional

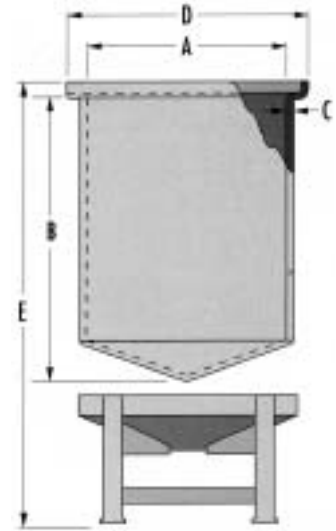

SYSTEM SPECIFICATIONS*

Catalog Number	TPCC00055	TPCC00100	TPCC00200	TPCC00250	TPCC00350	TPCC00500	TPCC00750	TPCC01000
Tank Volume (gallons)	55	100	200	250	350	500	750	1000
Construction Materials	Virgin, high-density polyethylene that is FDA approved							
Maximum Service Temp.	Rated to 160°F (70°C)							
<i>System Dimensions</i>								
Dia. (D) x Overall Height (E) (inches)	28x64	32x59	35x86	45x68	46x88	57x86	68x88	72x104
Wall Thickness	3/16"	1/4"	1/4"	5/16"	5/16"	3/8"	3/8"	3/8"
<i>Shipping Weight</i>								
Industrial (lbs.)	75	160	200	250	350	425	540	640
<i>Fittings (factory installed)</i>								
Fill Fitting	one-1"NPTF	one-1"NPTF	one-1.5"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF
Return Fitting	one-1"NPTF	one-1"NPTF	one-1.5"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF
Overflow Fitting	one-1"NPTF	one-1"NPTF	one-1.5"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF
Outlet Fitting	one-1"NPTF	one-1"NPTF	one-1.5"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF	one-2"NPTF
Vent Fitting	one-1"NPTF	one-1"NPTF	one-1"NPTF	one-1"NPTF	one-1"NPTF	one-1"NPTF	one-1"NPTF	one-1"NPTF
Level/Sight Fittings	two-.5" NPTF	two-.5" NPTF	two-.5" NPTF	two-.5" NPTF	two-.5" NPTF	two-.5" NPTF	two-.5" NPTF	two-.5" NPTF

Catalog Number	TPCC01500	TPCC02000
Tank Volume (gallons)	1500	2000
Construction Materials	Virgin, high-density polyethylene that is FDA approved	
Maximum Service Temp.	Rated to 160°F (70°C)	
<i>System Dimensions</i>		
D x H (inches)	79x99	86x103
Wall Thickness	7/16"	7/16"
<i>Shipping Weight</i>		
Industrial (lbs.)	875	1025
<i>Fittings (factory installed)</i>		
Fill Fitting	one-2"NPTF	one-2"NPTF
Return Fitting	one-2"NPTF	one-2"NPTF
Overflow Fitting	one-2"NPTF	one-2"NPTF
Outlet Fitting	one-2"NPTF	one-2"NPTF
Vent Fitting	one-1"NPTF	one-1"NPTF
Level/Sight Fittings	two-.5" NPTF	two-.5" NPTF

*Please contact Technical Support to obtain a drawing with exact fitting locations