


4 Channel Timer

General Description

Many simple water treatment programs can be applied using this versatile four channel timer. This convenient, economical unit has four individual outputs to control four pumps/valves etc. Each output is individually programmable with multiple control modes: 24 hour or 7 day schedule.

The double dual channel timer is designed for industrial use and comes complete with pigtails for easy installation and use. Push button programmability and the large digital readout makes set up and timer selections simple and easy.

General Layout

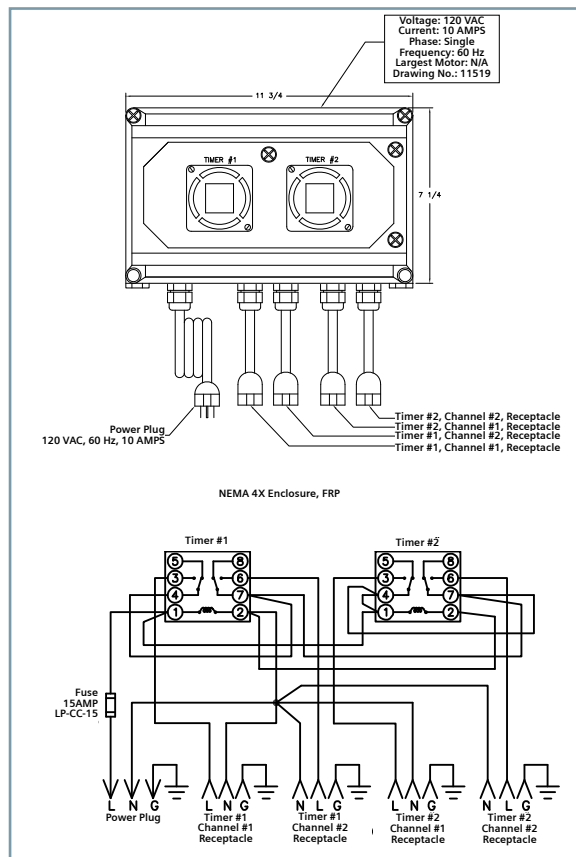

Specifications

Power	115 VAC / 60 Hz / 1 ph
Ambient temperature range	-29° to 60° C -20° to 140° F
Switch rating	10A / 250 VAC general purpose
Output	4 SPDT relays with dry contact
Accuracy	± 4 minutes per year

Data Sheet

Siemens
Water Technologies

Germany
+49 8221 9040
wtger.water@siemens.com

United Kingdom
+44 1732 771777
wtuk.water@siemens.com

USA
+1 800 809 0971
stranco.water@siemens.com

© 2008 Siemens Water Technologies Corp.
Literature No.: ST.470.415.000.IE.DS.1208
Subject to change without prior notice.

NEMA is a trademark of the National Electrical Manufacturers Association.

The information provided in this literature contains merely general descriptions or characteristics of performance which in actual case of use do not always apply as described or which may change as a result of further development of the products. An obligation to provide the respective characteristics shall only exist if expressly agreed in the terms of the contract.